




# SNFX-TZB Hexalobular Socket Flat Head Cap Screws

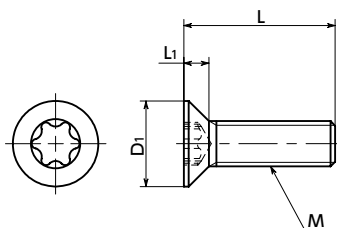

## Material/Finish



	SNFX-TZB
Main Body	Steel Trivalent Chromate Treatment
Strength Class	4.8 Equivalent





- Hexalobular socket shapes\*1 are designed to withstand high tightening torque compared to cross-recesses.
- Recesses are unlikely to be damaged due to tightening, allowing safe and secure tightening to be performed.

\*1 : The hexalobular shape is prescribed by JIS B 1015: 2008(ISO 10664: 2005)"Hexalobular internal driving feature for bolts and screws".

## Application

Prevention of damage to screw heads  
Reliable tightening

Unit : mm

Part Number 	M (Coarse)		L 										D <sub>1</sub>	L <sub>1</sub>	Hexalobular Socket No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch															
SNFX-M3-TZB	M3	0.5	5	6	8	10	12					6	1.75	10	0.32 - 0.60	20	
SNFX-M4-TZB	M4	0.7		6	8	10	12					8	2.3	20	0.72 - 1.2	20	
SNFX-M5-TZB	M5	0.8				10	12					10	2.8	25	1.9 - 2.2	20	
SNFX-M6-TZB	M6	1				10	12	20	25	30	35	12	3.4	30	2.5 - 7.5	20	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

## Related Products

**SKX** Hexalobular Wrench



**SKX-N** Hexalobular Wrench for Extremely Limited Access Spaces



**SKXB** Hexalobular Short Bit



**SRD** Magnet Screwdriver



## Part Number Specification

**SNFX-M6-20-TZB**

1 2 1

1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available