




# SPC-Z(INCH) Plastic Inch Threaded Rods - PC

Lightweight Electrical Insulation

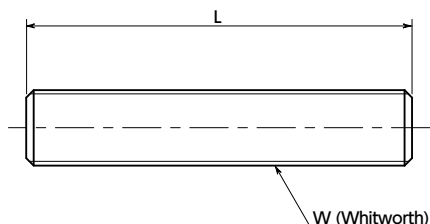

- PC (polycarbonate) threaded rods.
- Inch screw type.
- PC (polycarbonate) has the highest shock resistance of engineering plastics.
- Allowable operating temperature\*1 (min./max.): -40°C/115°C
- PC has low water absorbency and excellent weather resistance.
- For the properties and precautions for use of plastic screws, see "Properties of Plastic Screws."
- Application

Electrical and electronic equipment

## Material/Finish



	SPC-Z(INCH)
Main Body	PC (Polycarbonate) (Transparent)
Heat Resistance Temperature*1	115°C

\*1: This is the value for the resin material. The operating temperature of the product changes with performance conditions such as tightening torque.

Unit : mm

Part Number	W (Whitworth)		L	Mass (g)
	Nominal of Thread	Pitch		
SPC-W3 / 8-Z	W3/8	1.5875	300	25.06

## Part Number Specification

**SPC-W3/8-Z**



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
1 piece in 1 pack	Available / Add'l charge	Available / Add'l charge	Not Available	Not Available