




SNBS Socket Button Head Cap Screws

SUS Stainless steel

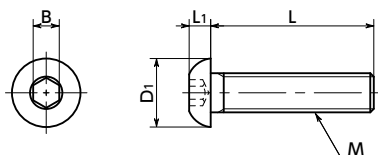

● Material/Finish



	SNBS
Main Body	Stainless Steel (A2)
Strength Class	A2 - 50

- Hex socket button head cap screws conforming to JIS B 1174.

Unit : mm

Part Number 1	M (Coarse)		L 2														D1	L1	B	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	6	8	10	12	20	16	25												
SNBS-M3	M3	0.5	6	8	10	12	20										5.7	1.65	2	0.49 - 1	20
SNBS-M4	M4	0.7	6	8	10	12	20	16	25								7.6	2.2	2.5	1 - 2.3	20
SNBS-M5	M5	0.8		8	10	12	20	16	25								9.5	2.75	3	2 - 3.9	20
SNBS-M6	M6	1			10	12	20	16	25	30	35	40					10.5	3.3	4	3.4 - 8.1	20
SNBS-M8	M8	1.25				12	20	16	25	30	35	40	45	50			14	4.4	5	7.7 - 19	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNBS-M3 - 8

1

2

1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge