


SNS-EL Hex Socket Head Cap Screws - Electroless Nickel Plating



High strength

High Specific Strength

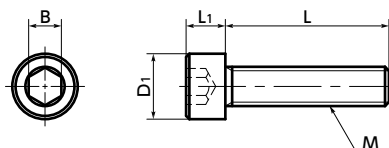

● Material/Finish



	SNS-EL
Main Body	SCM435 Electroless Nickel Plating
Strength Class	12.9

- Our unique processing technology enables screws to meet strength class 12.9 after surface treatment.
- For applications that require both high strength (Strength Class 12.9) and corrosion resistance.
- Complies with JIS B 1176, ISO 4762, and DIN 912. For details on shape and dimensions, please refer to the "Technical Information (JIS B 1176, ISO 4762)".

● Application

Equipment and device structures, FPD production equipment, semiconductor devices, and general industrial machines

Unit : mm

Part Number	M (Coarse)		L 												D1	L1	B	Mass (g)	Qty per pack
	Nominal of Thread 	Pitch																	
SNS-M3-EL	M3	0.5	5	6	8	10	12	16	20					5.5	3	2.5	0.67 - 1.4	20	
SNS-M4-EL	M4	0.7	5	6	8	10	12	16	20	25				7	4	3	1.4 - 3.2	20	
SNS-M5-EL	M5	0.8		6	8	10	12	16	20	25				8.5	5	4	2.2 - 4.8	20	
SNS-M6-EL	M6	1			8	10	12	16	20	25	30			10	6	5	4.3 - 8.3	10	
SNS-M8-EL	M8	1.25				10	12	16	20	25	30	35		13	8	6	10 - 19	10	
SNS-M10-EL	M10	1.5							20	25	30	35	40	16	10	8	23 - 33	10	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part number specification

SNS - M5 - 16 - EL

Product Code



Product Code

Individual Sales → P. xxxxx	Cleanroom Wash & Packaging → P. xxxxx	Screw Length Adjustment → P. xxxxx	Vibration Resistant → P. xxxxx	Modification process for captive use → P. xxxxx
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Please feel free to contact us