


SNPX-TZB-ALK

Hexalobular Socket Pan Head Machine Screws with Nylon Patch

 Vibration resistant treatment

e-nedzi.com®

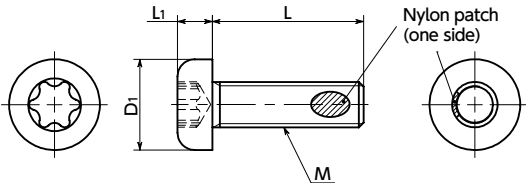

● Material/Finish

	SNPX-TZB-ALK
Main Body	Steel Trivalent Chromate Treatment
Nylon Patch	Nylon 11
Strength Class	4.8 Equivalent



- Hexalobular socket*1 pan head machine screws with nylon patch.
- Hexalobular socket shapes are designed to withstand high tightening torque compared to cross-recesses.
- Recesses are unlikely to be damaged due to tightening, allowing safe and secure tightening to be performed.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.

* 1 : The hexalobular shape is prescribed by JIS B 1015: 2008(ISO 10664: 2005)"Hexalobular internal driving feature for bolts and screws".

● Application

Prevention of damage to screw heads
Reliable tightening
Screw return and fallout prevented

Unit : mm

Part Number 	M (Coarse)		L 							D1	L1	Hexalobular Socket No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch												
SNPX-M3-TZB-ALK	M3	0.5	6	8	10					5.5	2	10	0.51 - 0.66	10
SNPX-M4-TZB-ALK	M4	0.7	6	8	10	12	16	20	25	7	2.6	20	0.91 - 2.3	10
SNPX-M5-TZB-ALK	M5	0.8		8	10	12	16	20	25	9	3.3	25	2.2 - 4.1	10
SNPX-M6-TZB-ALK	M6	1			10	12	16	20	25	10.5	3.9	30	3.6 - 6.2	10


- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.




● Related Products

 Hexalobular Wrench



 Hexalobular Wrench for Extremely Limited Access Spaces



 Hexalobular Short Bit



 Magnet Screwdriver








● Part Number Specification

SNPX-M5-20-TZB-ALK







 Individual Sales	 Cleanroom Wash & Packaging	 Screw Length Adjustment	 Vibration Resistant	 Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available



 <https://www.nbk1560.com>



 <https://www.nbk1560.com>