




SRS6A-ALK System 6 Screws with Nylon Patch

Non-Magnetic

Lightweight

Vibration resistant treatment

Tamper Resistance

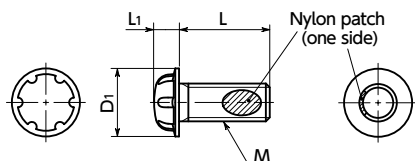

Material/Finish





	SRS6A-ALK
Main Body	A5056
Nylon Patch	Nylon 11



- Head has a special round shape with 6 grooves. With nylon patch.
- Made of aluminum alloy. The specific gravity is approximately 33% that of stainless steel.
- There is no electrocorrosion due to contact with aluminum alloy.
- Corrosion resistance, electrical conductivity, and thermal conductivity are excellent.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- This prevents mounting and removing with regular tools, including pliers.
- Install and remove with **SKRS6K** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver.
- Application

Equipment/devices disassembly/tampering prevention
Theft prevention for outdoor facilities
Security measures
Safety measures

Unit : mm

Part Number 	M (Coarse)		L 					D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch											
SRS6A-M3-ALK	M3	0.5	6	8	10			5.5	2.02	SKRS6A-3	SRD-6.35	0.16 - 0.18	10
SRS6A-M4-ALK	M4	0.7	6	8	10	12		7.5	2.5	SKRS6A-4	SRD-6.35	0.22 - 0.31	10
SRS6A-M5-ALK	M5	0.8		8	10	12	16	9.0	3.3	SKRS6A-5	SRD-6.35	0.29 - 0.38	10

• When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Related Products

SKRS6K applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



Part Number Specification

SRS6A-M5-16-ALK

Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available