


SNSS-RY Hex Socket Head Cap Screws - Low Temperature Black Chrome

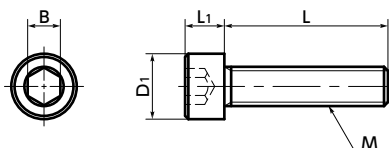

Vacuum
 Seizing Prevention
 Chemical-proof
 Antireflection
 SUS Stainless steel



● Material/Finish




	SNSS-RY
Main Body	SUSXM7 (S.S. Grade: A2) Low Temperature Black Chrome Treatment*1
Strength Class	A2-70

*1: The surface treatment for **SNSS-RY** has been changed to low temperature black chrome treatment.

● Tightening property (reference)

Part Number : SNSS-M5 - 25-RY

➔ P.xxxx

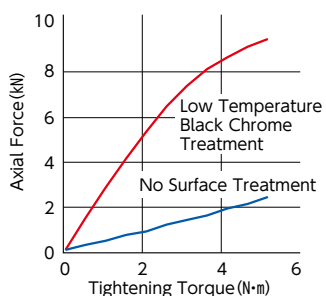

- Excellent corrosion resistance, chemical resistance, and abrasion resistance.
- Due to low outgas, screws can be used under vacuum environments.
- The coating has excellent lubricating ability and is suitable for prevention of seizing.
- Spectral reflectance is 1.5% or less. These screws are intended for optical instruments and other applications that require antireflection.
- Complies with JIS B 1176, ISO 4762, and DIN 912. For details on shape and dimensions, please refer to the "Technical Information (JIS B 1176, ISO 4762)".

● Application

Seizing prevention and reflection resistance,
Optical instruments, FPD production equipment,
and semiconductor devices

Unit : mm

Part Number	M (Coarse)		L													D1	L1	B	Mass (g)
	Nominal of Thread ①	Pitch	5	6	8	10	12	16	20	25	30	35	40						
SNSS-M3-RY	M3	0.5														5.5	3	2.5	0.67 - 1.4
SNSS-M4-RY	M4	0.7														7	4	3	1.5 - 3.2
SNSS-M5-RY	M5	0.8														8.5	5	4	2.5 - 4.8
SNSS-M6-RY	M6	1														10	6	5	4.7 - 8.3
SNSS-M8-RY	M8	1.25														13	8	6	12 - 19
SNSS-M10-RY	M10	1.5														16	10	8	23 - 33

● Part number specification

SNSS-M5-16-RY

Product Code ① ② Product Code

1 Individual Sales ➔ P.xxxx	Cleanroom Wash & Packaging ➔ P.xxxx	Screw Length Adjustment ➔ P.xxxx	Vibration Resistant ➔ P.xxxx	Modification process for captive use ➔ P.xxxx
1 piece in 1 pack	Available / Add'l charge	Not Available	Not Available	Please feel free to contact us