

SSHS-UCL


Socket Head Cap Screws with Ultra Low Profile - SUSXM7 - Cleanroom Washed & Packaged



Cleanroom wash & packaging



Stainless steel

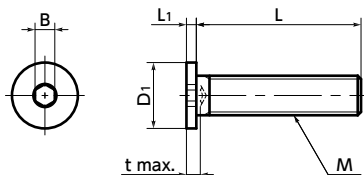

● Material/Finish



	SSHS-UCL
Main Body	SUSXM7 (Equivalent to SUS304) USC Cleaning
Strength Class	A2 - 50



- SUSXM7 hex socket head cap screw with special low profile.
- All head heights are 1.5 mm or less. For space-saving of equipment/devices and applications with limited overhead space.
- Cleanroom washed (ultrasonic cleaning) and cleanroom packaged.
- For parts embedded in FPD production devices, semiconductor manufacturing devices, medical equipment, or food machinery, or used in cleanrooms.
- SUS316L **SSHL-UCL** is available.

SSHL-UCL**SSHS-UCL**To distinguish it from **SSHS-UCL**, **SSHL-UCL** has a cup point tip.

● Application

Reducing the size of equipment and devices

FPD manufacturing equipment / Semiconductor manufacturing equipment / Medical equipment / Food related machinery

Unit : mm

Part Number 1	M (Coarse)		L 2										D1	L1	B	t max.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	4	5	6	8	10	12										
SSHS-M2-UCL	M2	0.4	4	5	6	8	10	12					4	1.1	1.3	1.2	0.11 - 0.29	10
SSHS-M2.5-UCL	M2.5	0.45	4	5	6	8	10	12					5	1.3	1.3	1.5	0.23 - 0.47	10
SSHS-M3-UCL	M3	0.5	4	5	6	8	10	12					6	1.3	1.5	2	0.36 - 0.69	10
SSHS-M4-UCL	M4	0.7			6	8	10	12	16				8	1.5	2	2.5	0.89 - 1.6	10
SSHS-M5-UCL	M5	0.8			6	8	10	12	16	20	25		9	1.5	3	3	0.73 - 3.3	10
SSHS-M6-UCL	M6	1			6	8	10	12	16	20	25	30	10	1.5	3	4	1.2 - 5.5	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SSHS-M5-12-UCL**1** Individual Sales**2** Cleanroom Wash & Packaging**3** Screw Length Adjustment**4** Vibration Resistant**5** Modification process for captive use

Available / Add'l charge

Cleanroom washed and packed

Available / Add'l charge

Not Available

Not Available