




SNS-J Socket Head Cap Screws

High strength High Specific Strength

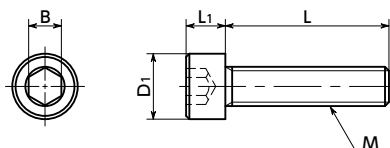

Material/Finish



	SNS-J
Main Body	SCM435 Ferrosoferric Oxide Film (Black)
Strength Class	12.9



- Complies with JIS B 1176, ISO 4762, and DIN 912. For details on shape and dimensions, please refer to the "Technical Information (JIS B 1176, ISO 4762)".
- Strength class is 12.9. High strength.
- M3 - M16. Selection from abundant size variations is available to suit the device or equipment.

Unit : mm

Part Number 	M (Coarse)		L 																D1	L1	B	Mass (g)		Qty per Pack
	Nominal of Thread	Pitch																						
SNS-M3	M3	0.5	4	5	6	8	10	12	16	20	25								5.5	3	2.5	0.65 - 1.5	50	
SNS-M4	M4	0.7		5	6	8	10	12	16	20	25	30	35						7	4	3	1.5 - 3.6	50	
SNS-M5	M5	0.8			6	8	10	12	16	20	25	30	35	40					8.5	5	4	2.9 - 6.6	50	
SNS-M6	M6	1				8	10	12	16	20	25	30	35	40	45	50			10	6	5	4.8 - 12	50	
SNS-M8	M8	1.25					10	12	16	20	25	30	35	40	45	50	60		13	8	6	11 - 26	20	
SNS-M10	M10	1.5						16	20	25	30	35	40	45	50	60			16	10	8	22 - 42	10	
SNS-M12	M12	1.75									30	35	40	45	50	60			18	12	10	41 - 61	5	
SNS-M16	M16	2											40	45	50	60	70	80	24	16	14	97 - 146	1	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SNS-M5-12

1 **2**

1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Not Available	Available / Add'l charge	Available / Add'l charge	Please feel free to contact us