




SPC-N-WH(INCH)

Plastic Inch Hex Nuts - PC

Lightweight Electrical Insulation

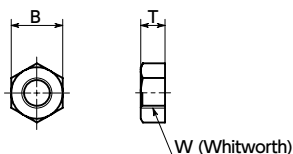

- PC (polycarbonate) hex nuts.
- Inch screw type.
- PC (polycarbonate) has the highest shock resistance of engineering plastics.
- Allowable operating temperature*1 (min./max.):
-40°C/115°C
- PC has low water absorbency and excellent weather resistance.
- For the properties and precautions for use of plastic screws, see "Properties of Plastic Screws."

● Application

Electrical and electronic equipment

● Material/Finish

RoHS

	SPC-N-WH(INCH)
Main Body	PC (Polycarbonate) (White)
Heat Resistance Temperature*1	115°C

*1: This is the value for the resin material. The operating temperature of the product changes with performance conditions such as tightening torque.

Unit : mm

Part Number	W (Whitworth)		B	T	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch				
SPC-W3 / 8-N-WH	W3/8	1.5875	17	8	1.8	10
SPC-W3 / 8-N-WH(200)	W3/8	1.5875	17	8	1.8	200

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SPC-W3/8-N-WH



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available