



SUS Stainless steel

TGY Male Screw

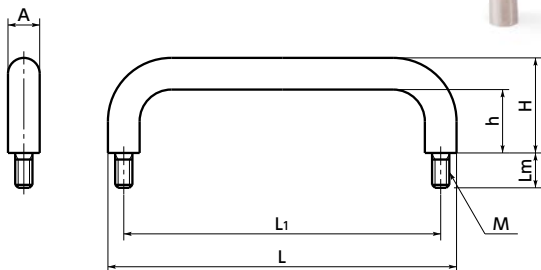

TG Female Screw

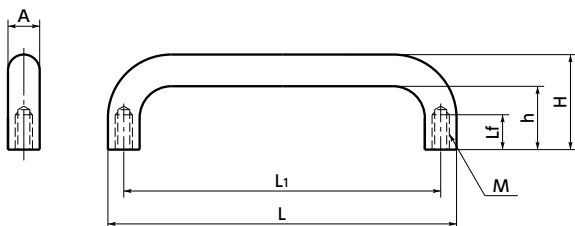

- Pull made of stainless steel.
- Use it in combination with the washer **LY-N** (→ P.xxxx).
*Washers are not supplied.
- Male screw/female screw can be selected according to the product code.
TGY — Male screw
TG — Female screw
- For **TG**, hex socket head cap screws for mounting (SUSXM7) are available as an option. Use the screw supply service (charged separately).

TGY Male Screw

Unit : mm

Part Number	L	A	L1	H	h	Lm	M	Allowable load*1 (N)	Mass (g)	Applicable Washer
TGY-86	86	6	80	30	24	10	M4	1000	30	LY-10
TGY-108	108	8	100	35	27	10	M5	1000	62	LY-12
TGY-110	110	10	100	30	20	11	M5	1000	89	LY-16A
TGY-128	128	8	120	40	32	10	M5	1000	74	LY-12
TGY-130	130	10	120	40	30	11	M6	1000	114	LY-16

*1 : Allowed load for a person.

TG Female Screw

Unit : mm

Part Number	L	A	L1	H	h	Lf	M	Allowable load*1 (N)	Mass (g)	Applicable Washer	Screw supply service Screw size
TG-24	24	4	20	22	18	7	M2.6	1000	4.5	—	M2.6×8
TG-46	46	6	40	22	16	7	M4	1000	14	LY-10-N	M4×8
TG-66	66	6	60	22	16	7	M4	1000	18.5	LY-10-N	M4×8
TG-86	86	6	80	30	24	10	M4	1000	26	LY-10-N	M4×12
TG-108	108	8	100	35	27	10	M5	1000	55.5	LY-12-N	M5×12
TG-110	110	10	100	30	20	11	M5	1000	82	LY-16-N	M5×12
TG-128	128	8	120	40	32	10	M5	1000	68	LY-12-N	M5×12
TG-130	130	10	120	40	30	11	M6	1000	104	LY-16-N	M6×12

*1 : Allowed load for a person.

● Material/Finish



	TGY / TG
Main body	Stainless Steel Buffing
Hex Socket Head Cap Screws (Screw supply service)	SUSXM7

● Part number specification

TG-24



TG-24-P



Screw supply service

When using the screw supply service (charged separately), add **-P** to the end of the product code.

Cleanroom Wash & Packaging → P.xxxx

Please feel free to contact us

Laser Marking → P.xxxx

Available / Add'l charge