




SNS-TZB Socket Head Cap Screws

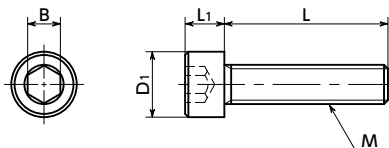

● Material/Finish



	SNS-TZB
Main Body	SCM435 Trivalent Chromate Treatment
Strength Class	10.9

- Complies with JIS B 1176, ISO 4762, and DIN 912. For details on shape and dimensions, please refer to the "Technical Information (JIS B 1176, ISO 4762)".
- M3 - M16. Selection from abundant size variations is available to suit the device or equipment.

Unit : mm

Part Number	M (Coarse)		L																D1	L1	B	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	5	6	8	10	12	16	20	25	30	35	40	45	50	60	70	80					
SNS-M3-TZB	M3	0.5	5	6	8	10	12	16	20	25									5.5	3	2.5	0.72 - 1.5	20
SNS-M4-TZB	M4	0.7	5	6	8	10	12	16	20	25	30	35							7	4	3	1.6 - 3.6	20
SNS-M5-TZB	M5	0.8		6	8	10	12	16	20	25	30	35	40						8.5	5	4	2.8 - 6.5	20
SNS-M6-TZB	M6	1			8	10	12	16	20	25	30	35	40	45	50				10	6	5	4.9 - 12	20
SNS-M8-TZB	M8	1.25				10	12	16	20	25	30	35	40	45	50	60			13	8	6	12 - 26	20
SNS-M10-TZB	M10	1.5						16	20	25	30	35	40	45	50	60			16	10	8	23 - 42	5
SNS-M12-TZB	M12	1.75									30	35	40	45	50	60			18	12	10	41 - 61	5
SNS-M16-TZB	M16	2											40	45	50	60	70	80	24	16	14	97 - 146	1

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNS-M5-12-TZB



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Please feel free to contact us	Available / Add'l charge	Available / Add'l charge	Please feel free to contact us