




SRGFS Five - Lobe Socket with Pin Flat Head Screws

Tamper Resistance **SUS** Stainless steel

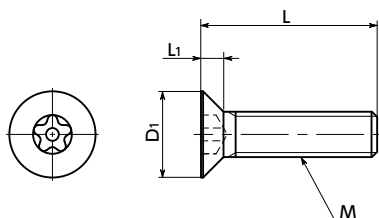

Material/Finish



	SRGFS
Main Body	SUSXM7
Strength Class	Equivalent to A2-50



- Countersunk head screws with a pin at the center of the five slots, inspired by plum blossoms. Also suitable for decorative uses.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRGB** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver together.

Application

Equipment/devices disassembly/tampering prevention
Theft prevention for outdoor facilities
Security measures
Safety measures

Unit : mm

Part Number	M (Coarse)		L							D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	10	16	20	25	30	40	50						
SRGFS-M4	M4	0.7	10	16	20					8	2.3	SRGB-M4	SRD-6.35	1.03 - 1.78	10
SRGFS-M5	M5	0.8	10	16	25	40				10	2.8	SRGB-M56	SRD-6.35	1.73 - 5.27	10
SRGFS-M6	M6	1	12	16	20	30	40	50		12	3.4	SRGB-M56	SRD-6.35	3.04 - 9.63	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Related Products

Washer for Flat Head Screw

SWAS-RW is available.



SRGB applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



Part Number Specification

SRGFS-M5-16

1

2

1 Individual Sales	1 Cleanroom Wash & Packaging	1 Screw Length Adjustment	1 Vibration Resistant	1 Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available