



SRS5S-ALK System 5 Screws with Nylon Patch



Vibration resistant treatment




Miniature Size



Tamper Resistance



SUS Stainless steel

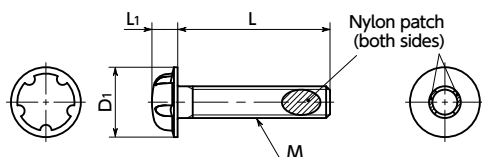

Material/Finish



RoHS

	SRS5S-ALK
Main Body	SUSXM7
Nylon Patch	Nylon 11
Strength Class	Equivalent to A2-50



- Head has a special round shape with 5 grooves. With nylon patch.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- This prevents mounting and removing with regular tools, including pliers.
- Install and remove with **SKRS5K** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver.

Application

Equipment/devices disassembly/tampering prevention
 Theft prevention for outdoor facilities
 Security measures
 Safety measures

Unit : mm

Part Number 1	M (Coarse)		L 2										D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	3	4	5	6	8	10	12	16	20	25						
SRS5S-M2-ALK	M2	0.4	3	4	5	6	8	10	12	16			4.5	1.45	SKRS5K-2	SRD-6.35	0.16 - 0.38	10
SRS5S-M2.5-ALK	M2.5	0.45	3	4	5	6	8	10	12	16	20		5.5	2.02	SKRS5K-3	SRD-6.35	0.29 - 0.78	10
SRS5S-M2.6-ALK	M2.6	0.45	3	4	5	6	8	10	12	16	20		5.5	2.02	SKRS5K-3	SRD-6.35	0.33 - 0.85	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Related Products

SKRS5K applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



Part Number Specification

SRS5S-M2 - 16 - ALK

1 **2** **1**

1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available