



## ● 材質・仕上げ

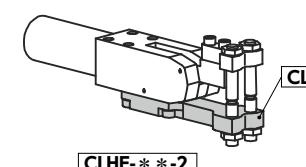

	CLHE
本体	ステンレス(S45C相当) 無電解ニッケルメッキ
パワークランパー用 センタリングガイドブッシュ [CLGB]	ステンレス 四三酸化鉄皮膜(黒)
六角穴付きボルト	ステンレス 四三酸化鉄皮膜(黒)

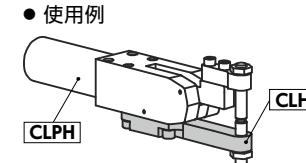

## ● 適用サイズ

品番	パワークランパー適用サイズ
CLHE-32	CLPV-20
CLHE-42	CLPV-32
CLHE-52	CLPV-40
CLHE-62	CLPV-50



品番①	B	A	A <sub>1</sub>	A <sub>2</sub>	B <sub>1</sub>	B <sub>2</sub>	B <sub>3</sub>	d	M <sub>1</sub>	M <sub>2</sub>	L	H	質量(g)
CLHE-32-1	32	98.5	34	53	15	22	—	7	M8	M5	8	10	130
CLHE-32-2	32	98.5	34	53	30	22	17	7	M8	M5	8	10	150
CLHE-42-1	42	140	51	74.4	19	30	—	9	M10	M6	8.5	14	220
CLHE-42-2	42	140	51	74.4	40	30	23	9	M10	M6	8.5	14	410
CLHE-52-1	52	168	62	88.5	22	37	—	11	M12	M8	12.5	16	380
CLHE-52-2	52	168	62	88.5	50	37	30	11	M12	M8	12.5	16	900
CLHE-62-1	62	192.5	71.5	102	22	44	—	13	M12	M10	12.5	18	690
CLHE-62-2	62	192.5	71.5	102	60	44	40	13	M12	M10	12.5	18	1020

単位:mm

## ● 関連商品

パワークランパー用センタリングガイ  
ドブッシュ [CLGB] があります。

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

CLHE-32-1

①